

SVS VALVE PLUG FORM BI 11MM FIELD-WIREABLE

24V LED+RC PG9



Form BI (11 mm)
max. 24 V AC/DC
LED and RC
PG9

Plastic housings with good resistance against chemicals and oils.


The resistance to aggressive media should be individually tested for your application. Further details on request.

[Link to Product](#)

Illustration

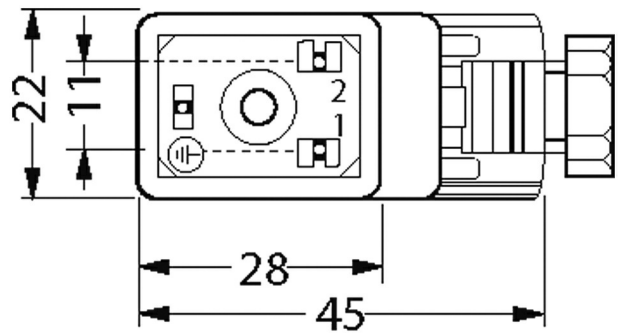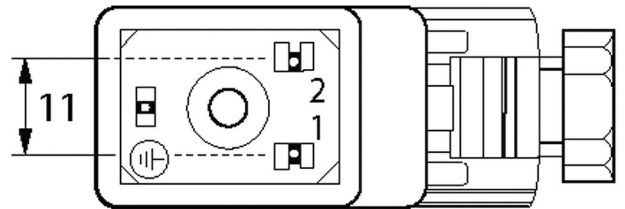

Height: 41 mm

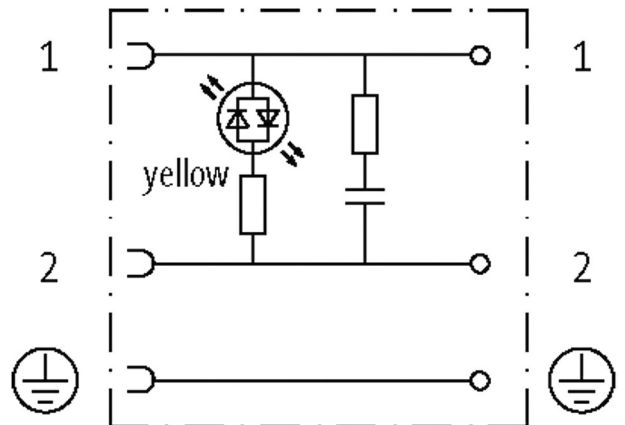

Product may differ from Image

Form

Form 29861

General data

Temperature range -20...+60 °C

Technical Data

Operating voltage max. 24 V AC/DC

Operating current per contact max. 2 A

Configuration 2 contacts + PE

Locking of ports M3 (recommended torque 0.4 Nm)

Protection IP65 inserted and tightened (EN 60529)

Commercial data

country of origin CZ

customs tariff number 85366990

EAN 4048879187152

eClass 27279221

Packaging unit 1