

SVS ECO VALVE PLUG FORM C 8MM 230V

2+PE field-wireable M16x1.5

Form C (8 mm)

250 V AC/DC

without components

metric



field-wireable

Plastic housings with good resistance against chemicals and oils.


The resistance to aggressive media should be individually tested for your application. Further details on request.

[Link to Product](#)

Illustration

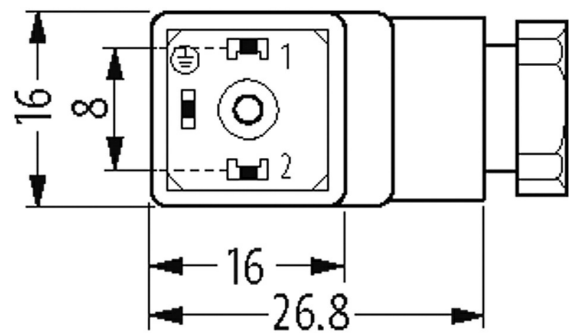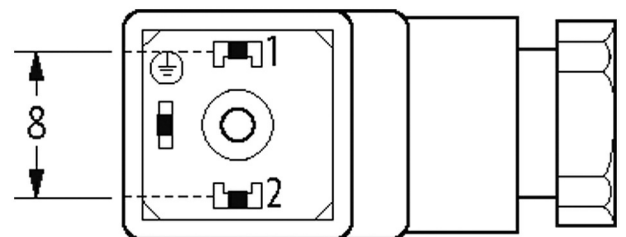

Height: 26 mm

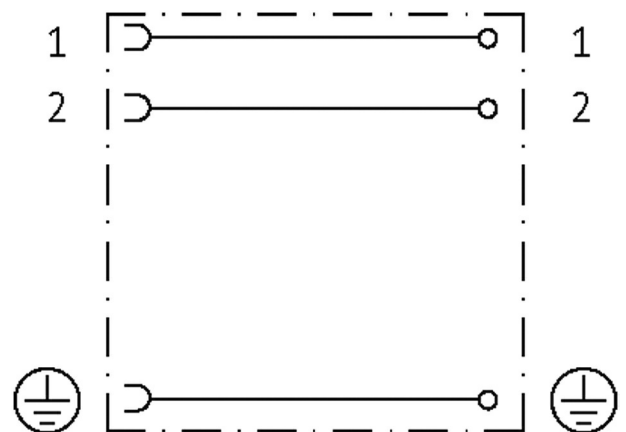

Product may differ from Image

Form

Form 30055

General data

Temperature range	-40...+90 °C
Material (gasket)	NBR
Mounting method	inserted, tightened
Printing	None

Technical Data

Operating voltage	max. 250 V AC/DC
Operating current per contact	max. 6 A
Configuration	2 contacts + PE
Connection cross section	max. 0.5 mm ²
Sealing range (cable Ø)	4...6 mm
Locking of ports	M2.5 (recommended torque 0.4 Nm)
Compression gland	M12×1.5 mm
Tightening torque (clamp screw)	0.2 ±0.1 Nm
Tightening torque (cable compression gland)	1.6 ±0.2 Nm
Contact figure	Cable outlet can be turned in 90° steps
Protection	IP65 inserted and tightened (EN 60529)

Commercial data

country of origin	HU
customs tariff number	85366990
EAN	4048879187015
eClass	27279221
Packaging unit	1