

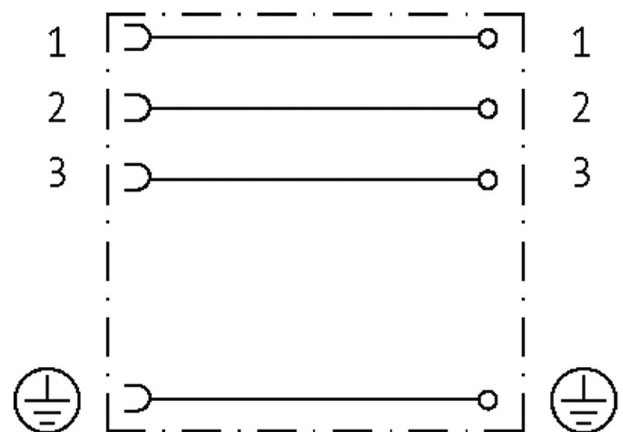
SVS ECO VALVE PLUG FORM CI 9.4 MM 110V

3+PE field-wireable M11x1.75

Form CI (9.4 mm)
110 V AC/DC
without components
metric
field-wireable

Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.

[Link to Product](#)**Illustration**

Product may differ from Image

Form

Form 30245

General data

Temperature range	-40...+90 °C
Material (gasket)	NBR
Mounting method	inserted, tightened
Printing	None

Technical Data

Operating voltage	110 V AC/DC
Operating current per contact	max. 6 A
Configuration	3 + PE
Connection cross section	max. 0.5 mm ²
Sealing range (cable Ø)	5...6 mm
Locking of ports	M3 (recommended torque 0.4 Nm)
Compression gland	M12×1.5 mm
Tightening torque (clamp screw)	0.2 ±0.1 Nm
Tightening torque (cable compression gland)	1.6 ±0.2 Nm
Contact figure	Cable outlet can be turned in 90° steps
Protection	IP65 inserted and tightened (EN 60529)

Commercial data

country of origin	HU
customs tariff number	85366990
EAN	4048879513715
eClass	27279221
Packaging unit	1