

M12 MALE 0° / M12 FEMALE 90°

PVC 5X0.34 bk UL/CSA 1.5m

Male straight – female 90°

M12 – M12, 5-pole

Art-No. 7005 - M12 Lite - (plastic hexagonal screw) on request

Plastic housings with good resistance against chemicals and oils.



The resistance to aggressive media should be individually tested for your application. Further details on request.

Further cable lengths on request.

Illustration

Product may differ from Image



Sketch

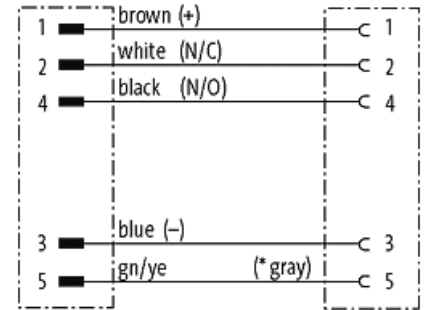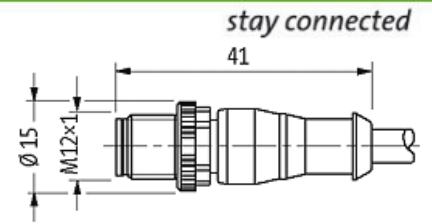

(* for cable type 126, 732, 219, 619)

Male

Female

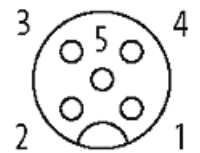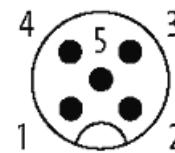

Product may differ from Image