

T COUPLER M12 MALE / M12 FEMALE 0°

T-coupler

Male straight – females straight

M12 – M12, 4-pole


Series connection

Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.

Illustration

Product may differ from Image

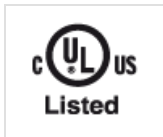Approvals**Form**

Form 41161

Technical Data

Operating voltage max. 60 V AC/DC

Operating voltage (only UL listed) 30 V AC/DC

Rated surge voltage 1.5 kV

Operating current per contact max. 4 A

Material group IEC 60664-1, category I

Locking of ports Screw thread (M12×1 mm) recommended torque 0.6 Nm, self-securing

Protection IP67 inserted and tightened (EN 60529)

Locking material Zinc die casting, matte nickel plated

General data

Temperature range -25...+85 °C

Commercial data

country of origin DE

customs tariff number 85366990




EAN 4048879144827

eClass 27143423

Packaging unit 1

Sketch

stay connected

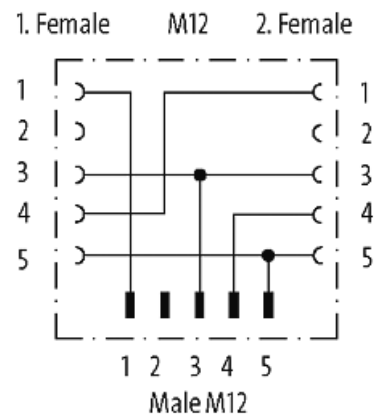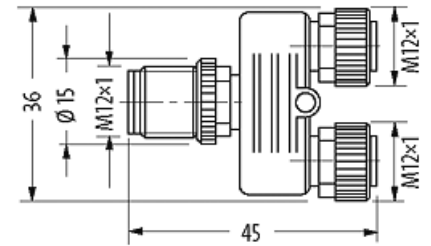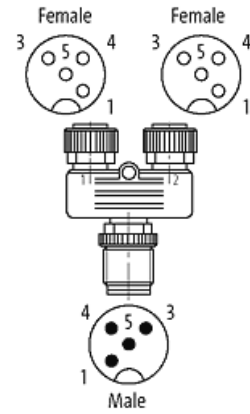

Product may differ from Image