

**T-COUPLER SLIMLINE M12 MALE / 2X M12 FEMALE**

T-coupler (Slim Line)

Male straight – females straight


M12 – M12, 4-pole

Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.

**Illustration**

Product may differ from Image

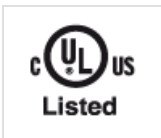**Approvals****Form**

Form 41171

**Technical Data**

Operating voltage max. 60 V AC/DC

Operating current per contact max. 4 A

Locking of ports Screw thread (M12×1 mm) recommended torque 0.6 Nm, self-securing

Protection IP65 and IP67 when plugged and screwed down (EN 60529)

Rated surge voltage 1.5 kV

**General data**

Temperature range -25...+85 °C

**Commercial data**

country of origin DE



customs tariff number 85366990

EAN 4048879144803

eClass 27143423

Packaging unit 1

**Sketch**

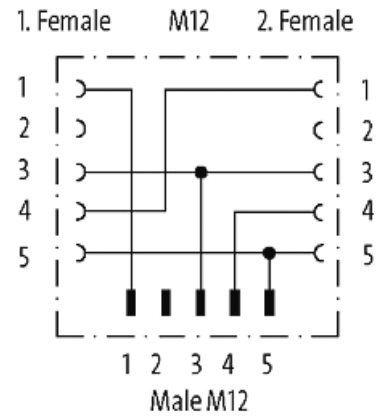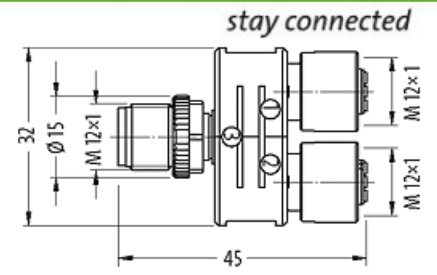

Product may differ from Image