

T-COUPLER SLIMLINE M12-MALE 5P./ 2X M12-FEMALE 5P.

T-coupler (Slim Line)


Male straight – females straight

M12 – M12, 5-pole

Distribution function (NO)

Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.

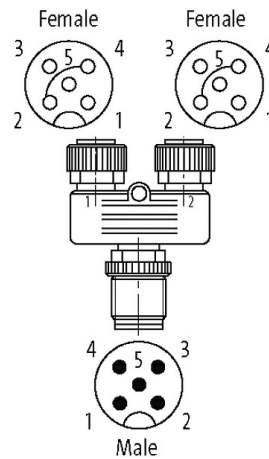Illustration

Product may differ from Image

Approvals**Form**

Form 41191

Technical Data

Operating voltage	max. 60 V AC/DC
Operating voltage (only UL listed)	30 V AC/DC
Rated surge voltage	1.5 kV
Operating current per contact	max. 4 A
Locking of ports	Screw thread (M12×1 mm) recommended torque 0.6 Nm, self-securing
Protection	IP67 inserted and tightened (EN 60529)

General data

The information in this brochure has been compiled with the utmost care.



Liability for the correctness completeness and topicality of the information is restricted to gross negligence. Version: 10/20

Temperature range	-25...+85 °C
-------------------	--------------

Commercial data

country of origin	DE
customs tariff number	85366990
EAN	4048879144797
eClass	27143423
Packaging unit	1

Sketch

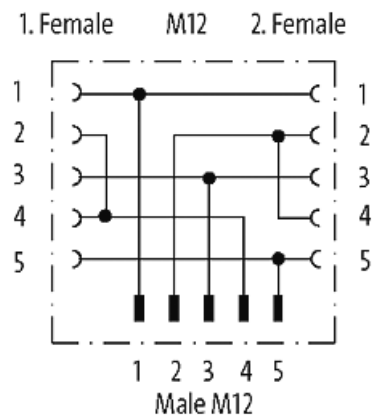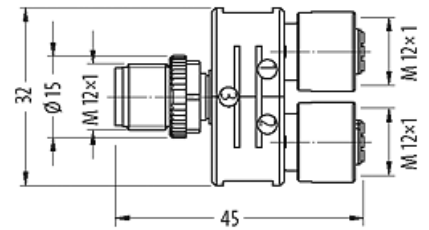

Product may differ from Image