

ADAPTOR M12MALE/M12FEMALE FOR DIAGNOSE CUBE67

Adapter

Male - female

M12 – M12, 4-pole (circuit diagram)

Bridge PIN 1 + 2

Illustration

Product may differ from Image

Form

Form 41241

Technical Data

Operating voltage	max. 250 V AC/DC
Rated surge voltage	2.5 kV
Operating current per contact	max. 4 A
Material group	IEC 60664-1, category I
Locking of ports	Screw thread (M12×1 mm) recommended torque 0.6 Nm, self-securing
Protection	IP67 inserted and tightened (EN 60529)
Material	PUR
Locking material	Zinc die casting, matte nickel plated


General data

Pollution Degree	3
Mounting method	inserted, tightened
Temperature range	-25...+85 °C
Test isolation voltage	0.8 kV eff/rms

Commercial data

country of origin	DE
customs tariff number	85366990
EAN	4048879144742
eClass	27143423
Packaging unit	1

Sketch

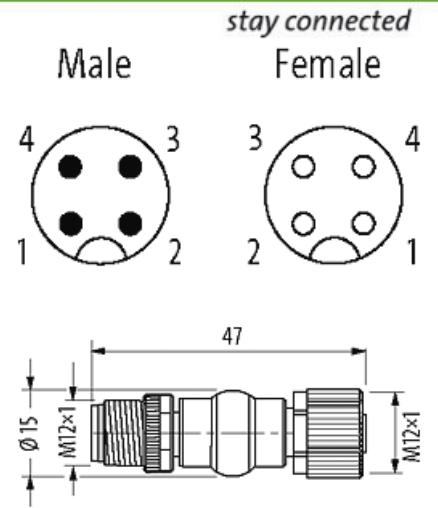

Product may differ from Image