

**adaptor M12 male/ M12 female 4p.**

Adapter




Male - female

M12 – M12, 4-pole (circuit diagram)

**Illustration**

Male

Female

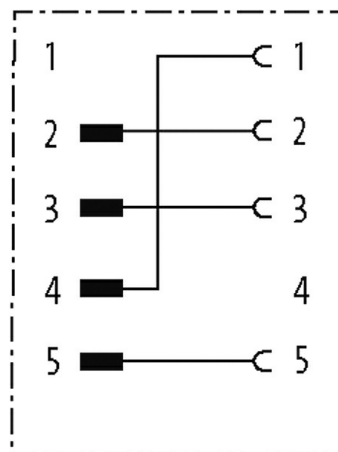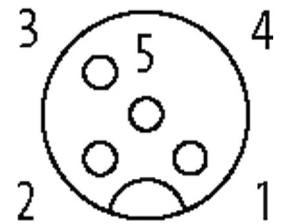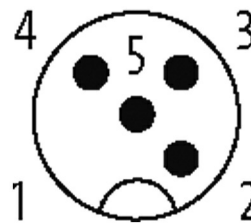

Product may differ from Image

**Approvals****Technical Data**

Operating voltage

max. 125 V AC/DC


Operating voltage (only UL listed)	30 V AC/DC
Rated surge voltage	0.8 kV
Operating current per contact	max. 4 A
Material group	IEC 60664-1, category I
Coding	A-coded
Locking of ports	Screw thread (M12×1 mm) recommended torque 0.6 Nm, self-securing
Compression gland	M12 (SW13)
Protection	IP67 inserted and tightened (EN 60529)
Material	PUR
Locking material	Zinc die casting, matte nickel plated

**General data**

Mounting method	inserted, tightened
Pollution Degree	3
Temperature range	-25...+85 °C

**Commercial data**

country of origin	DE
customs tariff number	85366990
EAN	4048879601993
eClass	27143423
Packaging unit	1

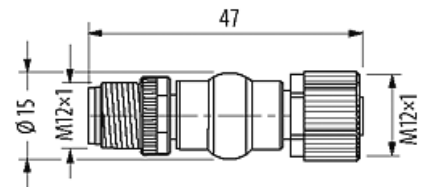**Sketch**

Product may differ from Image