

M12 ADAPTOR ON REAR OF MSUD VALVE PLUG FORM A 18MM

Form A (18 mm) – M12, connector at the rear
for pressure switches

24 V DC $\pm 25\%$

LED (yellow/green)



5-pole

Plastic housings with good resistance against chemicals and oils.


The resistance to aggressive media should be individually tested for your application. Further details on request.

Illustration

stay connected

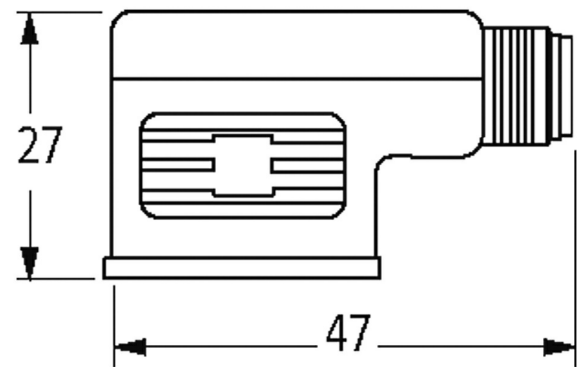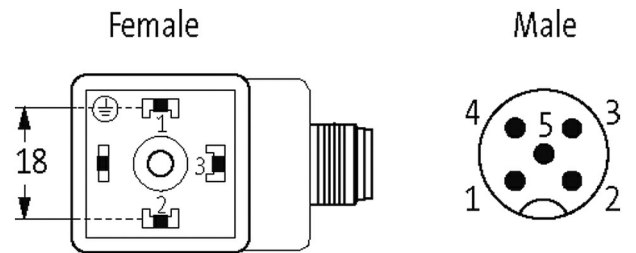

Depth: 27 mm

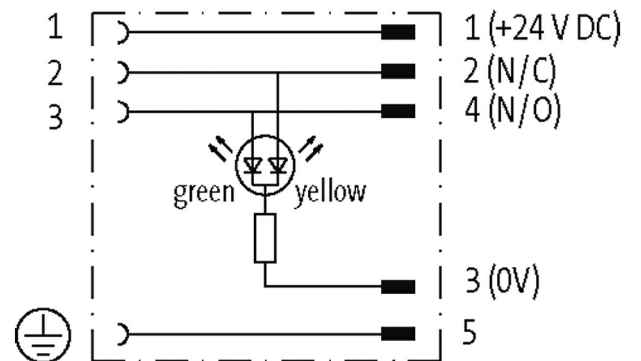

Product may differ from Image

Approvals

**Form**

Form	41441
------	-------

Technical Data

Operating voltage	24 V DC $\pm 25\%$
Rated surge voltage	0.8 kV
Operating current per contact	max. 4 A
Configuration	3 contacts + PE
Locking of ports	M3/M12 \times 1 mm (recommended torque 0.4/0.6 Nm)
Protection	IP67 inserted and tightened (EN 60529)

General data

Temperature range	-25...+85 °C
-------------------	--------------

Commercial data

country of origin	CZ
customs tariff number	85366990
EAN	4048879144612
eClass	27143423
Packaging unit	1