

M12 MALE ON TOP OF MSUD VALVE PLUG FORM BI 11MM

Form BI (11 mm) – M12, connector top entry

24 V AC/DC $\pm 25\%$

LED

3-pole

Plastic housings with good resistance against chemicals and oils.



The resistance to aggressive media should be individually tested for your application. Further details on request.

Illustration




Female

Male

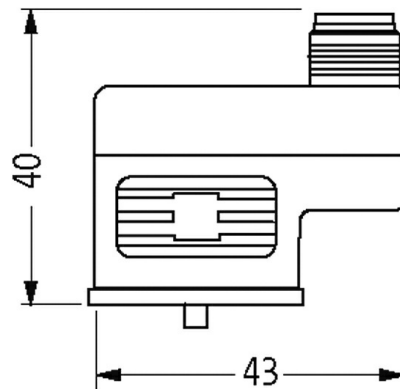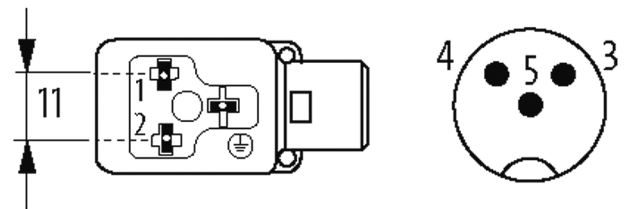

Depth: 22 mm

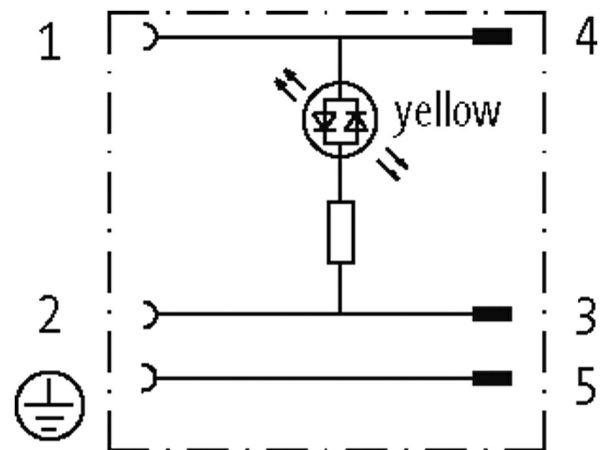

Product may differ from Image

Approvals

**Form**

Form 42001

General data

Temperature range -25...+85 °C

Technical DataOperating voltage 24 V AC/DC $\pm 25\%$

Operating current per contact max. 4 A

Configuration 2 contacts + PE

Protection IP67 inserted and tightened (EN 60529)

Locking of ports M3/M12×1 mm (recommended torque 0.4/0.6 Nm)

Commercial data

country of origin CZ

customs tariff number 85389099

EAN 4048879143318

eClass 27143423

Packaging unit 1