

**M12 ADAPTOR ON REAR / MSUD VALVE PLUG 9.4 MM**

Form CI (9.4 mm) – M12, connector at the rear

24 V AC  $\pm 20\%$  / DC  $\pm 25\%$

LED and suppression

3-pole

Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.



**Illustration**

*stay connected*




Female

Male

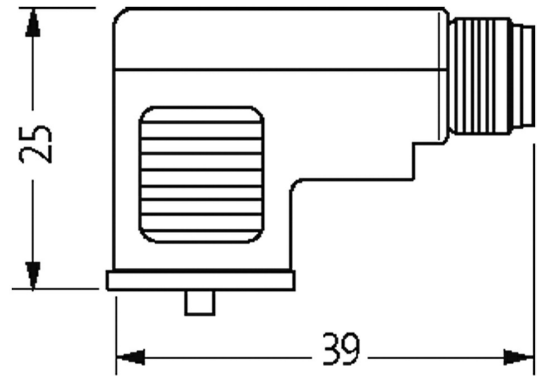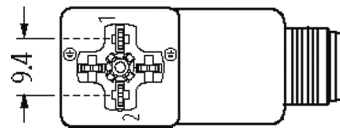

Depth: 15 mm

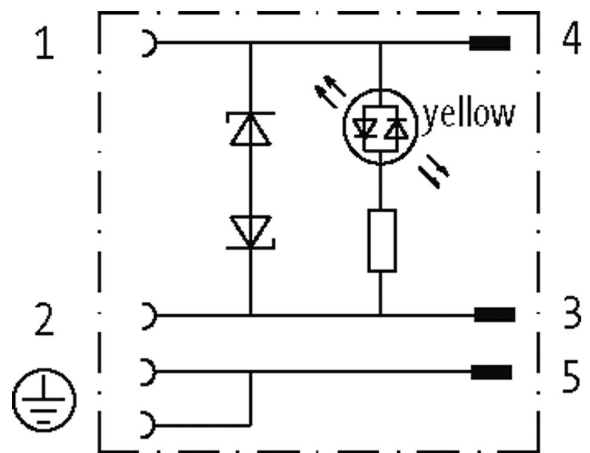

Product may differ from Image

**Approvals**

**Form**

Form 42871

**Technical Data**

Operating voltage	24 V AC $\pm 20\%$ / DC $\pm 25\%$
Operating current per contact	max. 4 A
Current consumption	max. 15 mA
Configuration	2 contacts + PE
Switch off peak	max. 55 V
Locking of ports	M3/M12 $\times$ 1 mm (recommended torque 0.4/0.6 Nm)
Protection	IP67 inserted and tightened (EN 60529)

**General data**

Temperature range -25...+85 °C

**Commercial data**

country of origin	CZ
customs tariff number	85366990
EAN	4048879348737
eClass	27143423
Packaging unit	1