

**T-coupler M12 male / M12 male - female PROFIBUS**

T-coupler

Male straight – female/male straight

M12 – M12, 5-pole

B-coded

shielded

Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.

**Illustration**

Product may differ from Image

**More Info****Form**

Form 44151

**Technical Data**

Operating voltage	5 V DC (via the fieldbus device)
Operating current per contact	max. 12.5 mA
No. of poles	5
Material group	IEC 60664-1, category I
Transfer rate	12 Mbps
Coding	B-coded
Locking of ports	Screw thread (M12×1 mm) recommended torque 0.6 Nm, self-securing
Compression gland	M12 (SW13)
Protection	IP67 inserted and tightened (EN 60529)
Locking material	Zinc die casting, matte nickel plated

**General data**

Mounting method	inserted, tightened
Pollution Degree	3
Temperature range	-25...+85 °C


**Commercial data**

country of origin	DE
customs tariff number	85366990
EAN	4048879141413
eClass	27143423

Packaging unit

1

**Sketch**

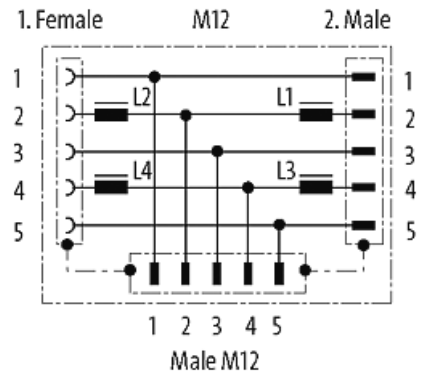

Product may differ from Image