

M12 male / M12 female 0° shielded Cube67

PUR 0.5+0.25 shielded gn UL/CSA+drag ch. 27m

Cube67

Male straight – female straight

M12 – M12, 6-pole

shielded



A-coded

Hybrid cable

Plastic housings with good resistance against chemicals and oils.


The resistance to aggressive media should be individually tested for your application. Further details on request.

Further cable lengths on request.

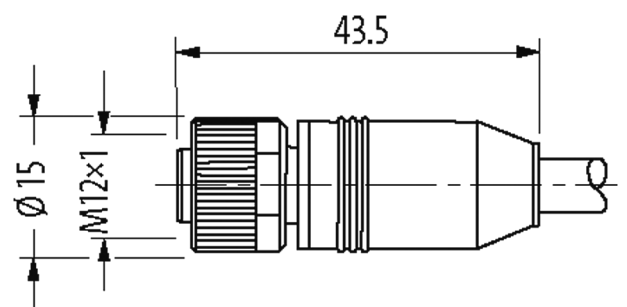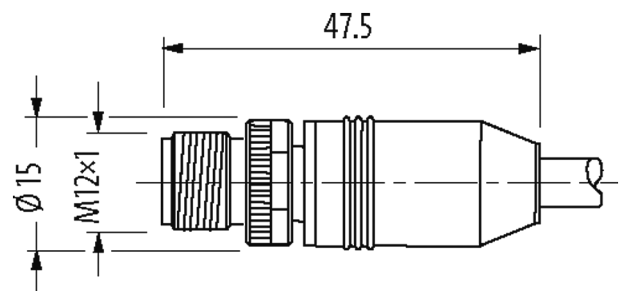[Link to Product](#)**Illustration**



Product may differ from Image

Sketch

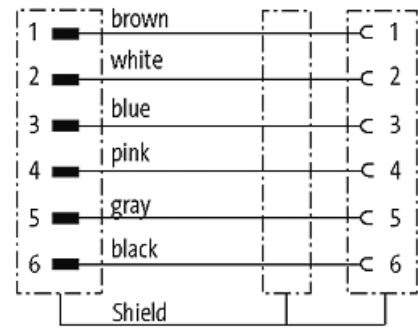

Male

Female

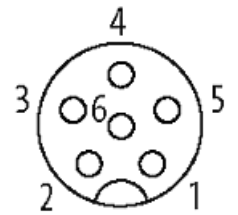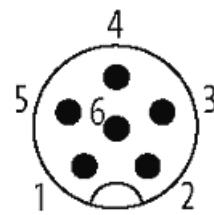

Product may differ from Image