

T-COUPLER M12 6POL. CUBE67 SHIELDED

Cube67

T-coupler

Male straight – female/male straight

M12 – M12, 6-pole

A-coded

shielded

Cube67 additional actuator power supply

Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.

[Link to Product](#)**Illustration**

Product may differ from Image

Form

Form 46091

General data

Temperature range -25...+85 °C

Technical Data

Operating voltage max. 60 V AC/DC

Operating current per contact max. 4 A

Locking of ports Screw thread (M12×1 mm) recommended torque 0.6 Nm, self-securing

Protection IP67 inserted and tightened (EN 60529)

Rated surge voltage 1.5 kV

Commercial data

country of origin DE




customs tariff number 85366990

EAN 4048879628594

eClass 27143423

Packaging unit 1

Sketch

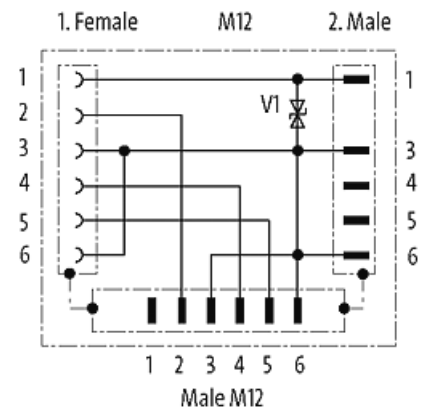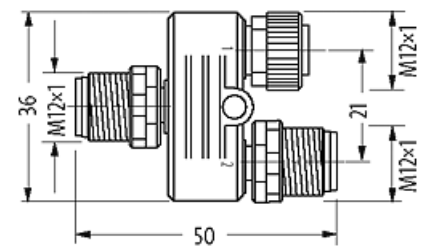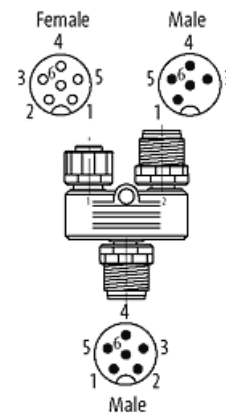

Product may differ from Image