

M12 MALE 0° / M12 FEMALE 0° SHIELDED

PUR 8x0,25 shielded gy UL/CSA, drag ch 25m

Male straight – female straight

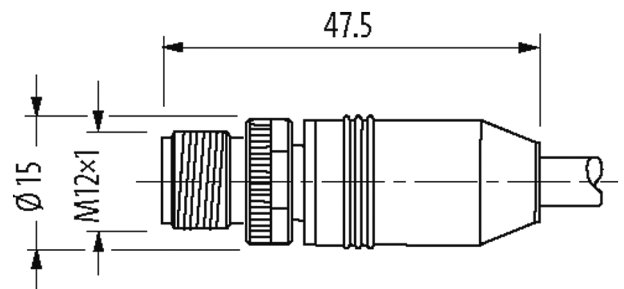
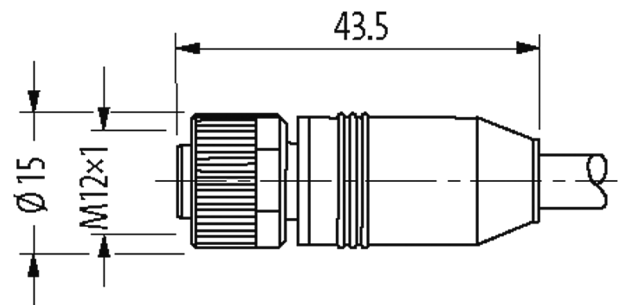
M12 – M12, 8-pole

shielded

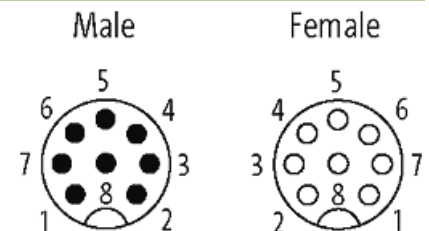
Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.

Further cable lengths on request.

Link to Product**Illustration**

Product may differ from Image

Sketch

Product may differ from Image