

T-coupler M12 male / M12 female 8p. shielded

T-coupler

Male straight – females straight


M12 – M12, 8-pole

shielded

Parallel circuit

Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.

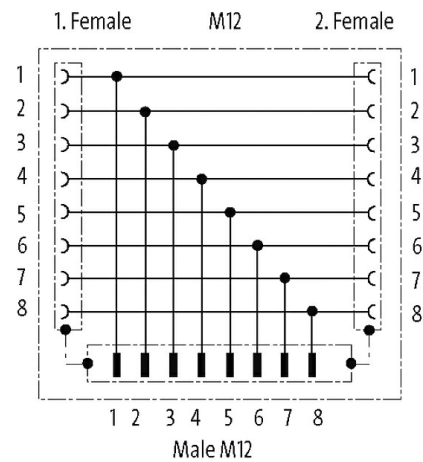[Link to Product](#)**Illustration**

Product may differ from Image

Approvals

* only for products with UL/CSA approved cable

Form

Form 48161

General data

Temperature range -25...+85 °C

Technical Data


Operating voltage max. 30 V AC/DC

Operating voltage (only UL listed)	max. 30 V AC/DC
Operating current per contact	max. 2 A
Locking of ports	Screw thread (M12×1 mm) recommended torque 0.6 Nm, self-securing
Protection	IP67 inserted and tightened (EN 60529)
Rated surge voltage	0.8 kV

Commercial data

country of origin	DE
customs tariff number	85366990
EAN	4048879470841
eClass	27143423
Packaging unit	1

Sketch

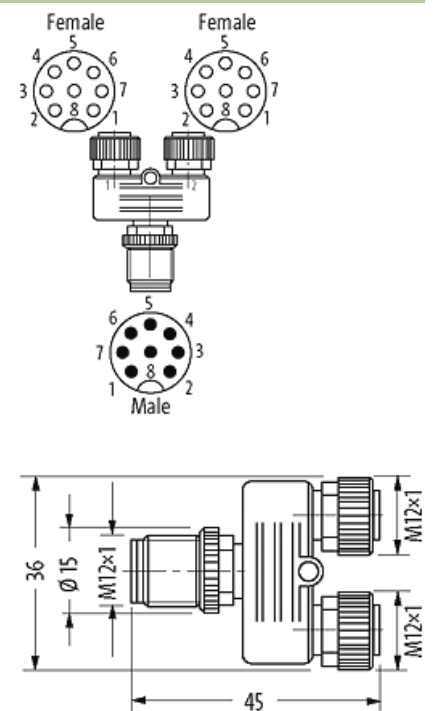

Product may differ from Image