

7/8"-T-COUPLER

T-coupler

Female straight – female/male straight

7/8" – 7/8", 5-pole

Parallel circuit

Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.

[Link to Product](#)

Illustration



Product may differ from Image

Form

Form 50061

General data

Mounting method inserted, tightened
Temperature range -20...+80 °C




Technical Data

Operating voltage max. 50 V AC/DC
Operating current per contact max. 8 A
Protection IP67 inserted and tightened (EN 60529)
Locking material Zinc die casting

Commercial data

country of origin CN
customs tariff number 85366990
EAN 4048879138130
eClass 27143423
Packaging unit 1

Sketch

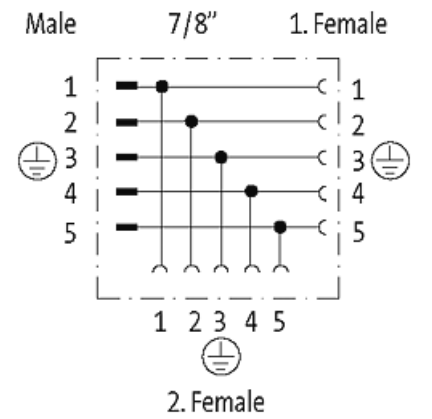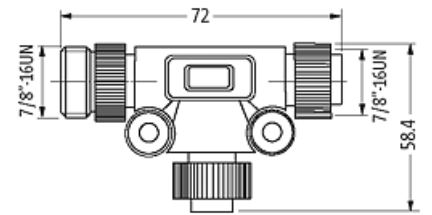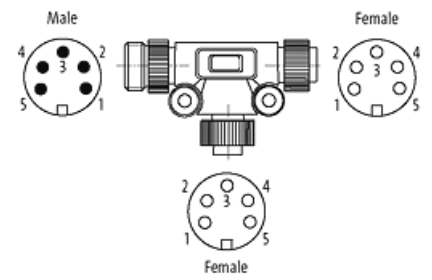

Product may differ from Image