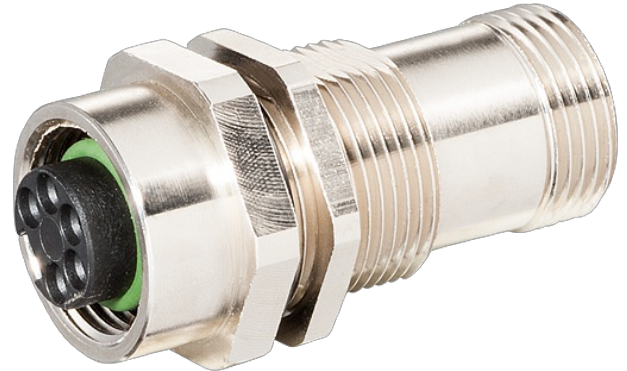


**7/8"-BULKHEAD FLANGE PLUG 5 POLE**

Control cabinet entry system

Female - male

7/8" (5-pole)

[Link to Product](#)**Illustration**

Product may differ from Image

**Form**

Form 50111

**General data**

Pollution Degree 3

Temperature range -20...+80 °C

**Technical Data**

Operating voltage max. 230/400 V AC/DC

Rated surge voltage 3.0 kV

Operating current per contact max. 12 A

Material group IEC 60664-1, category I

Locking of ports Screw thread 7/8" (recommended torque 1.5 Nm) self-securing

Protection IP67 inserted and tightened (EN 60529)

**Commercial data**

country of origin CZ




customs tariff number 85366990

EAN 4048879138123

eClass 27279220

Packaging unit 1

**Sketch**

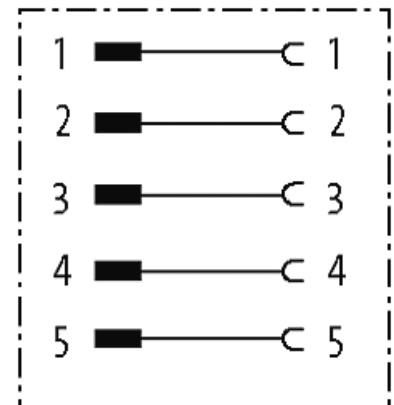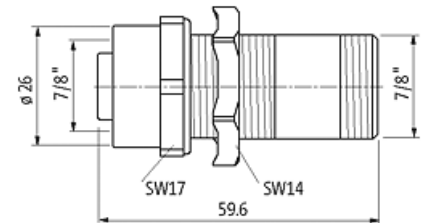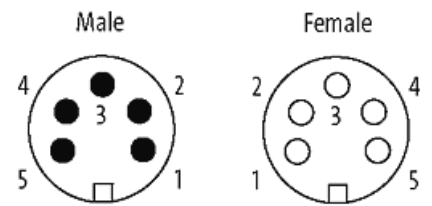

Product may differ from Image