

RJ45 Heavy Duty male 0° 4pol. Profinet

PROFINET

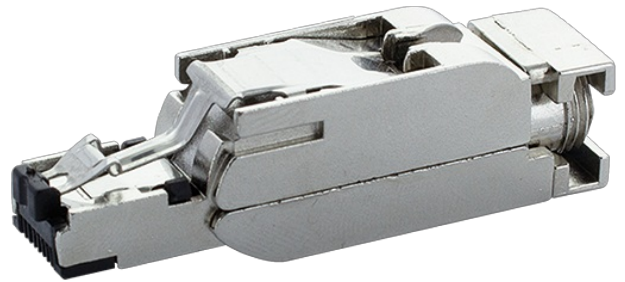
Male straight

RJ45, 4-pole

Field-wireable

Protection IP20

The resistance to aggressive media should be individually tested for your application. Further details on request.

[Link to Product](#)**Illustration**

Product may differ from Image

More Info**General data**

Pollution Degree	2
Temperature range	-30...+70 °C
Dimensions H×W×D	14,02x16,4x56,5

Technical Data

No. of poles	4
Transfer rate	100 Mbit/s
Sealing range (cable Ø)	4x AWG24 / AWG22
Protection	IP20

Commercial data

country of origin	CN
customs tariff number	85366990
EAN	4048879830362
eClass	27279221
Packaging unit	1