

7/8" MALE 90° FIELD-WIREABLE SCREW

5-pol. clamp section 6-8,7mm

Male 90°

7/8" (5-pole)

Screw terminals

Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.

Illustration

Product may differ from Image

Approvals**Form**

Form 78141

General data

Temperature range -25...+85 °C

Technical Data

Operating voltage	max. 250 V AC/DC
Operating current per contact	max. 9 A
Connection cross section	max. 1.5 mm ²
Sealing range (cable Ø)	6...8.7 mm
Locking of ports	Screw thread 7/8" (recommended torque 1.5 Nm) self-securing
Protection	IP67 inserted and tightened (EN 60529)




Commercial data

country of origin	DE
customs tariff number	85366990
EAN	4048879134750
eClass	27279218
Packaging unit	1

Sketch

stay connected

Male

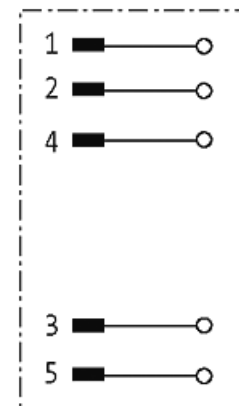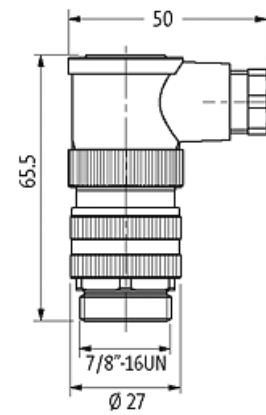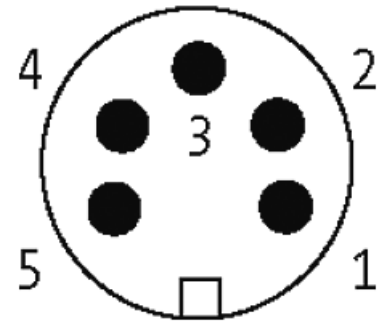

Product may differ from Image