

7/8" male 90° field-wireable

Male 90°

7/8" (5-pole)

Screw terminals

Sealing range (cable Ø): 8...10 mm

Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.

[Link to Product](#)**Illustration**

Product may differ from Image

Form

Form 78151

General data

Temperature range -25...+85 °C

Technical Data

Operating voltage max. 300 V AC/DC

Operating current per contact max. 9 A

Connection cross section max. 2.5 mm²

Sealing range (cable Ø) 8...10 mm

Locking of ports Screw thread 7/8" (recommended torque 1.5 Nm) self-securing

Protection IP67 inserted and tightened (EN 60529)

Material PBT

Commercial data

country of origin DE

customs tariff number 85366990




EAN 4048879631723

eClass 27279218

Packaging unit 1

Sketch

Male

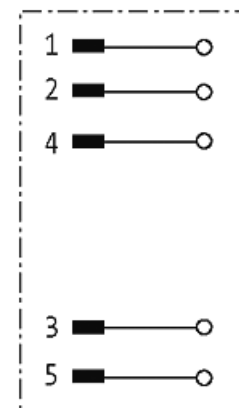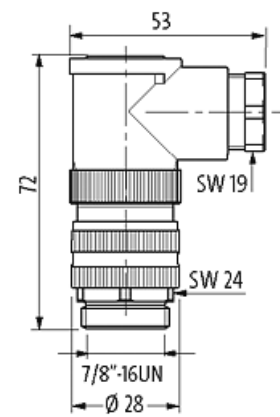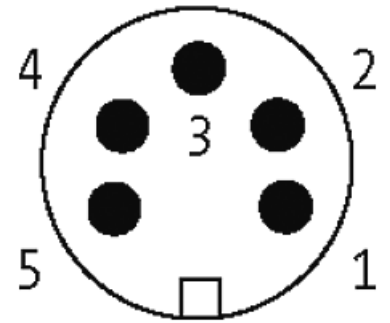

Product may differ from Image