

7/8" FEMALE 0° FIELD-WIREABLE SCREW

4-pol. clamp section 6-8 mm

Female straight

7/8" (3-pole)

Screw terminals

Plastic housings with good resistance against chemicals and oils.




The resistance to aggressive media should be individually tested for your application. Further details on request.

[Link to Product](#)

Illustration



Female

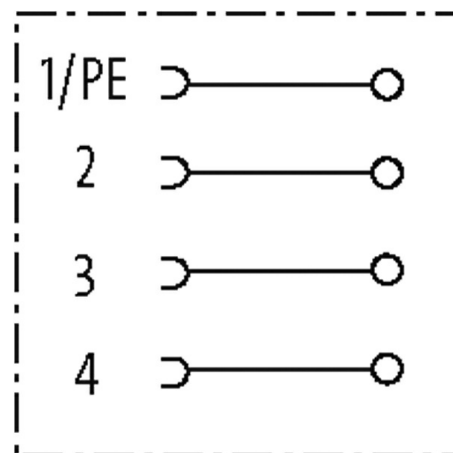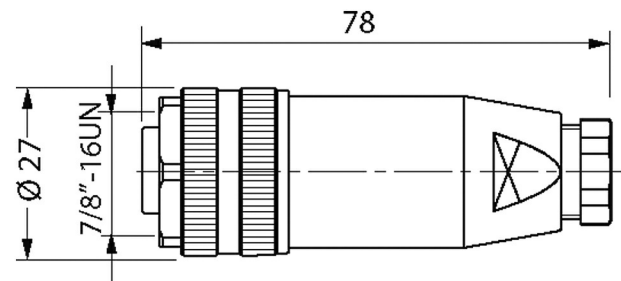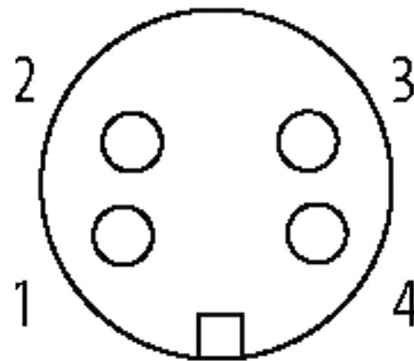

Product may differ from Image

Approvals


General data

Temperature range -25...+85 °C

Technical Data

Operating voltage max. 300 V AC/DC

Operating current per contact max. 9 A

Connection cross section max. 1.5 mm²

Sealing range (cable Ø) 6...8 mm

Protection IP67 inserted and tightened (EN 60529)

Locking of ports Screw thread 7/8" (recommended torque 1.5 Nm) self-securing

Commercial data

country of origin DE

customs tariff number 85366990

EAN 4048879134743

eClass 27279218

Packaging unit 1