

**7/8" FEMALE 90° FIELD-WIREABLE SCREW**

5-pol. clamp section 6-8mm

Female 90°

7/8" (5-pole)

Screw terminals

Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.

[Link to Product](#)**Illustration**

Product may differ from Image

**Approvals****Form**

Form 78261

**General data**

Temperature range -25...+85 °C

**Technical Data**

Operating voltage max. 250 V AC/DC

Operating current per contact max. 9 A

Connection cross section max. 1.5 mm<sup>2</sup>

Sealing range (cable Ø) 6...8.7 mm

Locking of ports Screw thread 7/8" (recommended torque 1.5 Nm) self-securing

Protection IP67 inserted and tightened (EN 60529)

Locking material Zinc die casting, matte nickel plated

**Commercial data**

country of origin DE

customs tariff number 85366990

EAN 4048879134705




eClass 27279218

Packaging unit

1

**Sketch**

Female

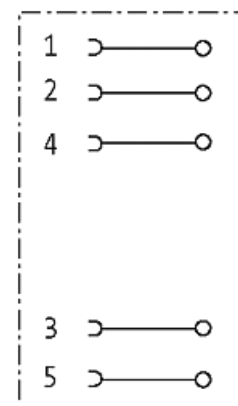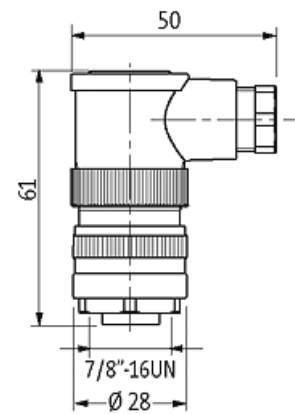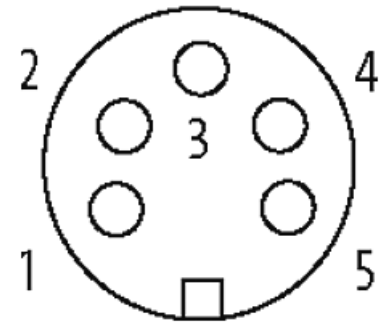

Product may differ from Image