

**7/8" female 90° field-wireable**

Female 90°

7/8" (5-pole)

Sealing range (cable Ø): 8...10 mm

Screw terminals

Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.

**Illustration**

Product may differ from Image

**Form**

Form 78271

**General data**

Temperature range -25...+85 °C

Material (gasket) FKM

**Technical Data**

Operating voltage max. 300 V AC/DC

Operating current per contact max. 9 A

Connection cross section max. 2.5 mm<sup>2</sup>

Sealing range (cable Ø) 8...10 mm

Locking of ports Screw thread 7/8" (recommended torque 1.5 Nm) self-securing

Protection IP67 inserted and tightened (EN 60529)

Material PBT

**Commercial data**

country of origin DE

customs tariff number 85366990

EAN 4048879631709




eClass 27279218

Packaging unit 1

**Sketch**

*stay connected*

## Female

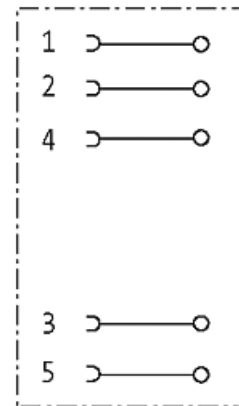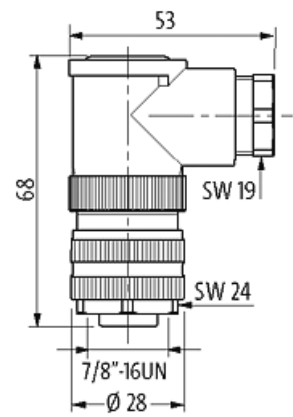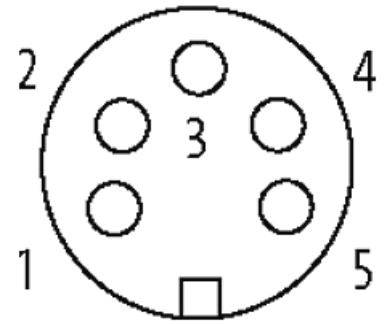

Product may differ from Image