

**7/8" MALE FLANGE PLUG**

Wire 5X0.75 0.2m

Flange male  
7/8" (5-pole)  
Front mounting  
with multi-strand wire

[Link to Product](#)**Illustration**

Product may differ from Image

**Form**

Form 78341

**General data**

Temperature range -25...+85 °C

**Cables**

Cable number 978

No./diameter of wires 5 x 0.75 mm<sup>2</sup>

Wire isolation PVC (br, wh, bl, bk, gnye)

Outer Ø 3.1 mm ±5%

Temperature range (fixed) -25...+85 °C

Temperature range (mobile) -10...+50 °C

Bend radius (fixed) 10 x outer Ø

**Technical Data**

Operating voltage max. 300 V AC/DC

Operating current per contact max. 6 A

Material group IEC 60664-1, category III

Locking of ports Screw thread 7/8" (recommended torque 1.5 Nm) self-securing

Compression gland 7/8" (SW24)


Protection IP68 inserted and tightened (EN 60529)

Connection pre-wired with PVC-wire isolation, (UL/CSA)


**Commercial data**

country of origin DE

customs tariff number	85444290
EAN	4048879134675
eClass	27279218
Packaging unit	1

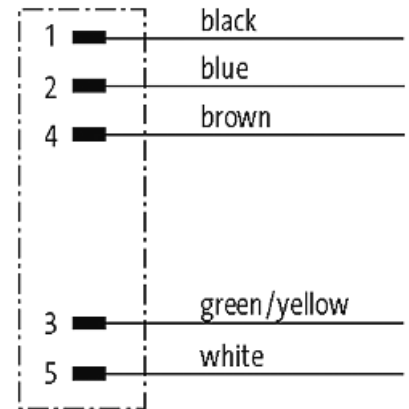**Sketch**

Male

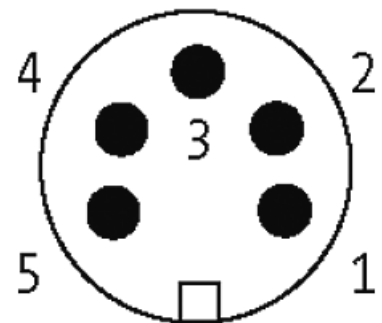

Product may differ from Image