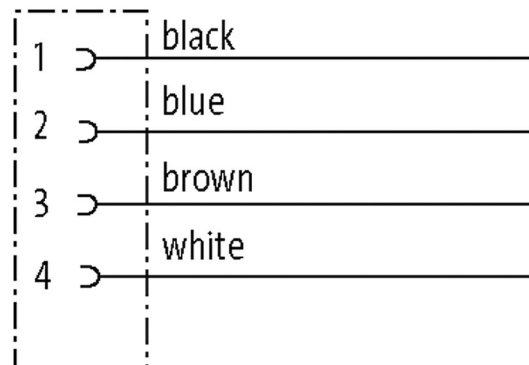
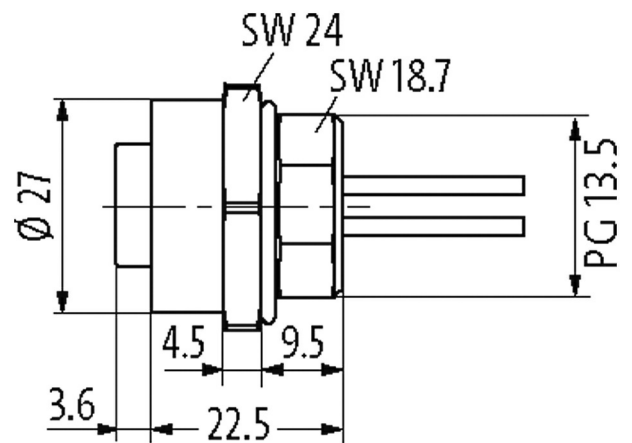


**7/8" FEMALE FLANGE PLUG**

Wire 4X0.75 0.5m

Flange female  
7/8" (4-pole)  
with multi-strand wire

[Link to Product](#)**Illustration**

Product may differ from Image

### Approvals



### Form

Form 78361

### General data

Temperature range -25...+85 °C

Pollution Degree 3

Material (contact) Brass, gold plated

### Cables

Cable number 977

No./diameter of wires 4 × 0.75 mm<sup>2</sup>

Wire isolation PVC (br, wh, bl, bk)

### Technical Data

Operating voltage max. 300 V; max. 600 V (UL)

Rated surge voltage 4.0 kV

Operating current per contact max. 7 A

Material group IEC 60664-1, category III

Locking of ports Screw thread 7/8" (recommended torque 1.5 Nm) self-securing

Compression gland 7/8" (SW24)

Protection IP68 inserted and tightened (EN 60529)

### Commercial data

country of origin DE


customs tariff number 85444290

EAN 4048879564052

eClass 27279218

Packaging unit 1

### Sketch

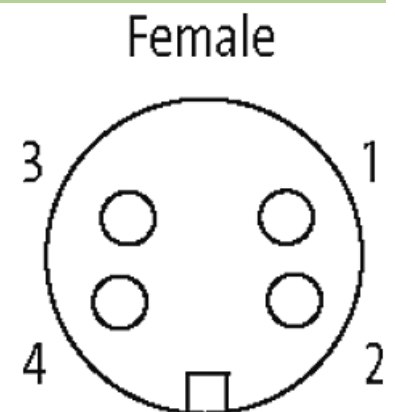

Product may differ from Image