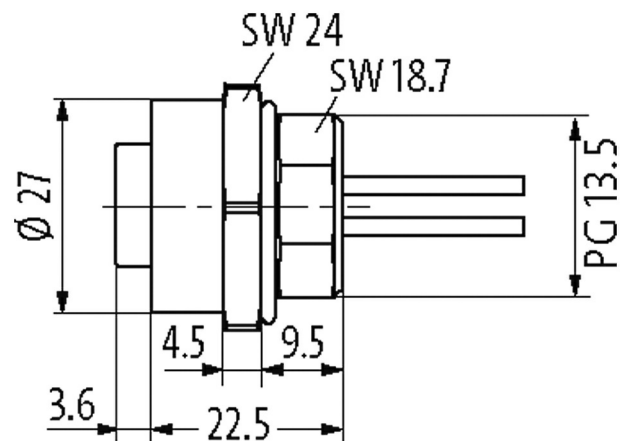


**7/8" FEMALE FLANGE PLUG**

Wire 5X0.75 3m

Flange female  
7/8" (5-pole)  
with multi-strand wire

[Link to Product](#)**Illustration**

Product may differ from Image

**Approvals****Form**

Form 78381

**General data**

Temperature range -25...+85 °C

Material (contact) Brass, gold plated

**Cables**

Cable number	978
No./diameter of wires	5 × 0.75 mm <sup>2</sup>
Wire isolation	PVC (br, wh, bl, bk, gnye)
Outer Ø	3.1 mm ±5%
Temperature range (fixed)	-25...+85 °C
Temperature range (mobile)	-10...+50 °C
Bend radius (fixed)	10 × outer Ø


**Technical Data**

Operating voltage	max. 300 V; max. 600 V (UL)
Rated surge voltage	4.0 kV
Operating current per contact	max. 6 A
Material group	IEC 60664-1, category III
Locking of ports	Screw thread 7/8" (recommended torque 1.5 Nm) self-securing
Compression gland	7/8" (SW24)
Protection	IP68 inserted and tightened (EN 60529)
Connection	pre-wired with PVC-wire isolation, (UL/CSA)


**Commercial data**

country of origin	DE
customs tariff number	85444290
EAN	4048879686112
eClass	27279218
Packaging unit	1

**Sketch**

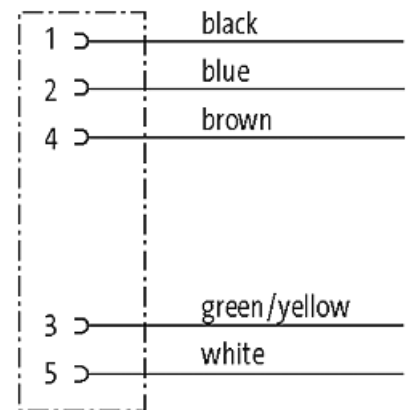

### Female

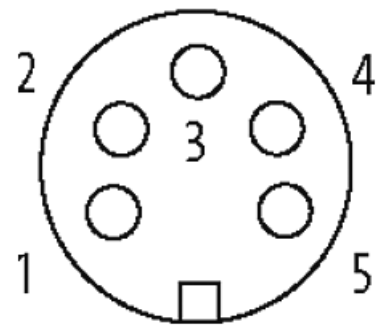

Product may differ from Image