

## M8 panel feed through 4p shielded

Control cabinet entry system

Male - female


M8, 4-pole

Rear mounting

shielded

### [Link to Product](#)

#### Illustration

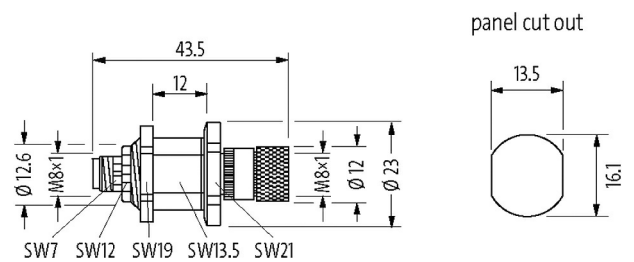

Product may differ from Image

#### Form

Form 88112

#### General data

Mounting plate thickness	1...12 mm
Mounting method	inserted, tightened
Material (contact carrier)	PA
Material (contact)	Copper alloy
Material (contact surface)	Au
Pollution Degree	3
Temperature range	-25...+85 °C


#### Technical Data

Operating voltage	250 V
Rated surge voltage	2.5 kV
Operating current per contact	max. 4 A
No. of poles	4
Material group	3
LED display	no
Compression gland	M8
Protection	IP67 inserted and tightened (EN 60529)

Housing	Metal
suitable for corrugated tube (internal Ø)	without
Over voltage category	2
Mating cycles	≥ 100

**Commercial data**

country of origin	DE
customs tariff number	85366990
EAN	4048879689304
eClass	27143423
Packaging unit	1

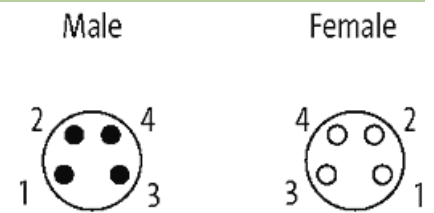**Sketch**

Product may differ from Image