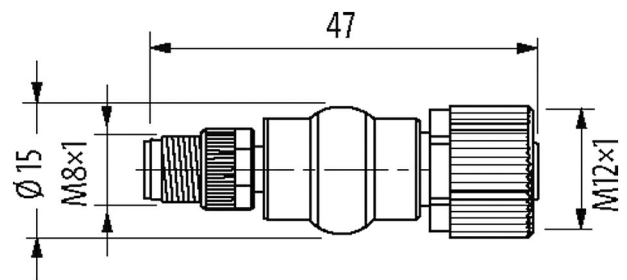
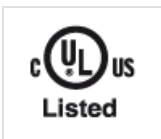


ADAPTOR M8 MALE 4 POLE/ M12 FEMALE CONF. 1,2,3,4

Adapter
 Male - female
 M8 – M12, 4-pole
 for M8 distribution box 4-pole

[Link to Product](#)**Illustration**

Product may differ from Image

Approvals**Form**

Form 88531

General data


Temperature range -25...+85 °C
 Test isolation voltage 0.8 kV eff/rms

Technical Data

Operating voltage	max. 50 V AC/60 V DC
Operating voltage (only UL listed)	max. 30 V AC/DC
Operating current per contact	max. 4 A
Locking of ports	Screw thread (M8/M12×1 mm) recommended torque 0.4/0.6 Nm, self-securing
Protection	IP67 inserted and tightened (EN 60529)
Locking material	Zinc die casting, matte nickel plated
Material	PUR

Commercial data

country of origin	DE
customs tariff number	85366990
EAN	4048879118514
eClass	27143423
Packaging unit	1

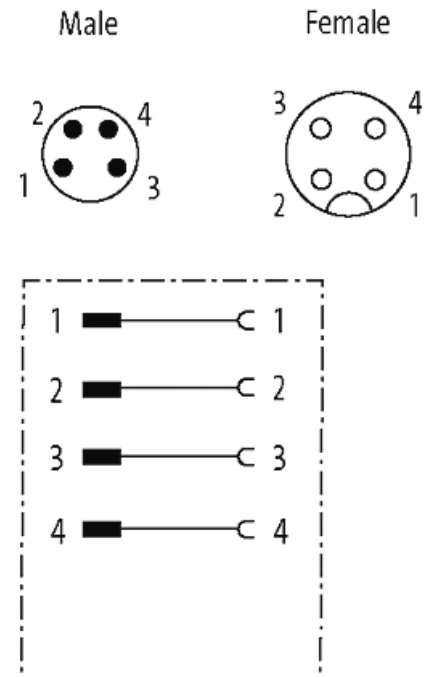Sketch

Product may differ from Image