

T-COUPLER NANO M8-MALE 4P/ 2X M8-FEMALE 3 POLE

T-coupler (Nano)

Male straight – females straight

M8 – M8, 4-pole

Distribution function (NO)

Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.

[Link to Product](#)**Illustration**

Product may differ from Image

Form

Form 88602

General data

Temperature range -30...+80 °C

Technical Data

Operating voltage max. 32 V AC/DC

Rated surge voltage 0.8 kV

Operating current per contact max. 2 A

Locking of ports Screw thread (M8×1 mm) self-securing

Protection IP67 inserted and tightened (EN 60529)

Commercial data

country of origin DE


customs tariff number 85366990

EAN 4048879118491

eClass 27143423

Packaging unit 1

Sketch

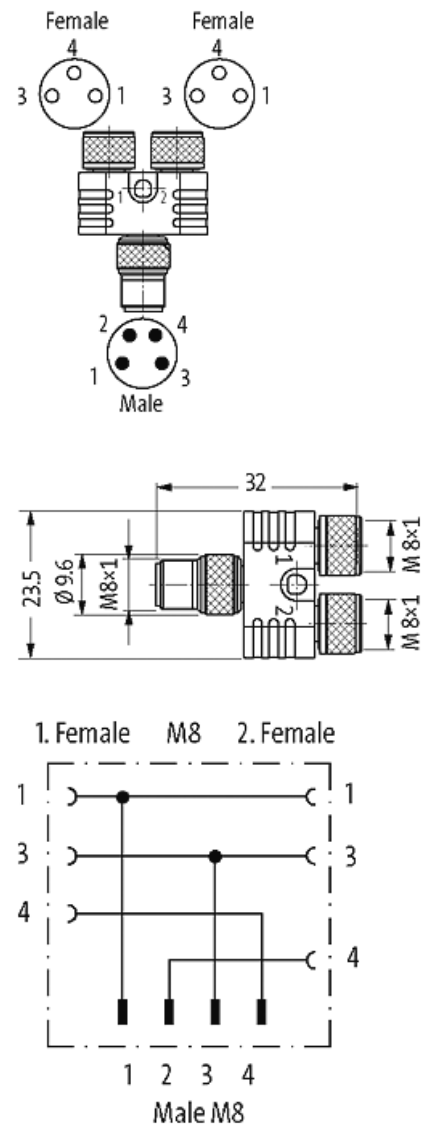

Product may differ from Image