

**T COUPLER MALE CON. M8 /FEMALE CON. M8**

T-coupler

Male straight – females straight

M8 – M8, 3-pole


Parallel circuit

Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.

[Link to Product](#)**Illustration**

Product may differ from Image

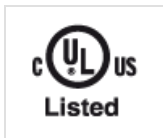**Approvals****Form**

Form 88611

**General data**

Pollution Degree 3

Temperature range -25...+85 °C

**Technical Data**

Operating voltage max. 50 V AC/60 V DC

Operating voltage (only UL listed) max. 30 V AC/DC

Rated surge voltage 1.5 kV

Operating current per contact max. 4 A

Locking of ports Screw thread (M8×1 mm) recommended torque 0.4 Nm, self-securing

Protection IP67 inserted and tightened (EN 60529)

**Commercial data**

country of origin DE




customs tariff number 85366990

EAN 4048879333177

eClass 27143423

Packaging unit 1

**Sketch**

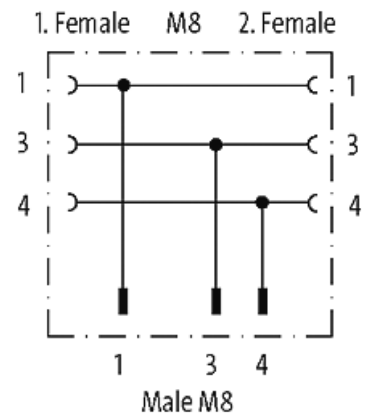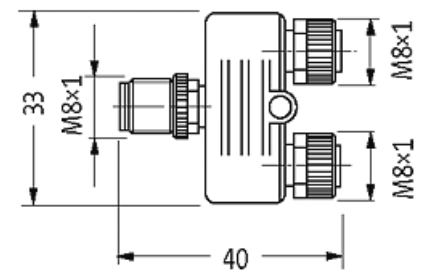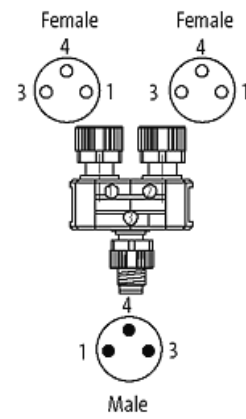

Product may differ from Image