

**M8 ADAPTOR ON REAR OF MSUD VALVE PLUG FORM A 18MM**

LED+Suppression 24 V AC/DC

Form A (18 mm) – M8, connector at the rear

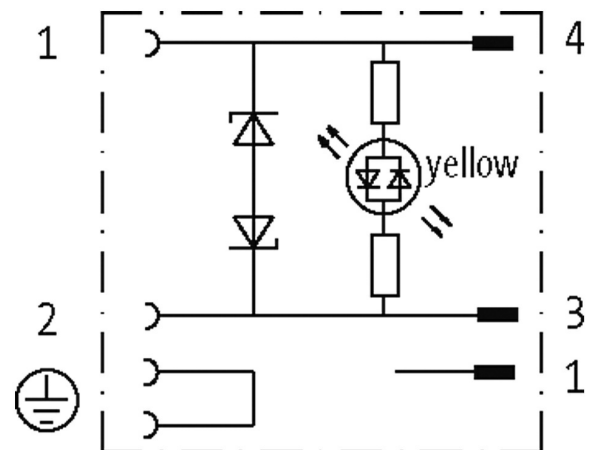
24 V AC  $\pm 20\%$  / DC  $\pm 25\%$ 

LED and suppression

3-pole

Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.

[Link to Product](#)**Illustration**

Product may differ from Image

**Approvals****Form**

Form

88915

**General data**

Temperature range -25...+85 °C

**Technical Data**

Operating voltage	24 V AC $\pm 20\%$ / DC $\pm 25\%$
Rated surge voltage	0.8 kV
Operating current per contact	max. 4 A
Current consumption	max. 15 mA
Configuration	2 contacts + bridged PE
Switch off peak	max. 55 V
Locking of ports	M3/M8 (recommended torque 0.4 Nm)
Protection	IP67 inserted and tightened (EN 60529)

**Commercial data**

country of origin	CZ
customs tariff number	85366990
EAN	4048879115971
eClass	27143423
Packaging unit	1