

M8 ADAPTOR ON REAR OF MSUD VALVE PLUG FORM BI 11MM

LED 24 V AC/DC

Form BI (11 mm) – M8, connector at the rear

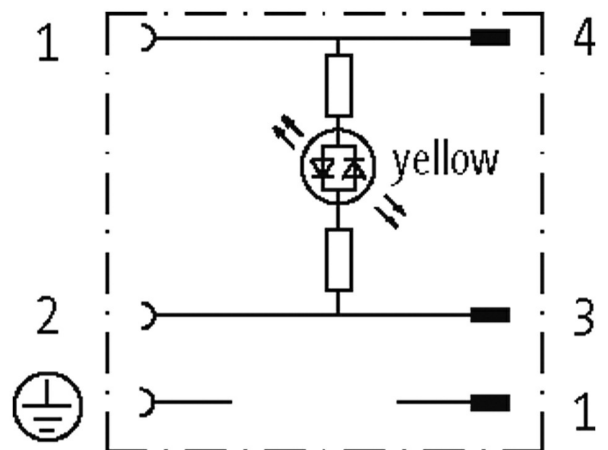
24 V AC/DC $\pm 25\%$

LED

3-pole

Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.

[Link to Product](#)**Illustration**

Product may differ from Image

Approvals**Form**

Form

88953

General data

Temperature range -25...+85 °C

Technical Data

Operating voltage	24 V AC/DC ±25%
Operating current per contact	max. 4 A
Configuration	2 contacts + PE
Locking of ports	M3/M8 (recommended torque 0.4 Nm)
Protection	IP67 inserted and tightened (EN 60529)
Rated surge voltage	0.8 kV

Commercial data

country of origin	CZ
customs tariff number	85366990
EAN	4048879115865
eClass	27143423
Packaging unit	1