

PUSH PULL POWER 5 POLE FIELD- WIREABLE

Male straight


PPP, 5-pole

Spring clamp terminals

Connection cross section: 0.75...2.5 mm²

Push Pull Power

The resistance to aggressive media should be individually tested for your application. Further details on request.

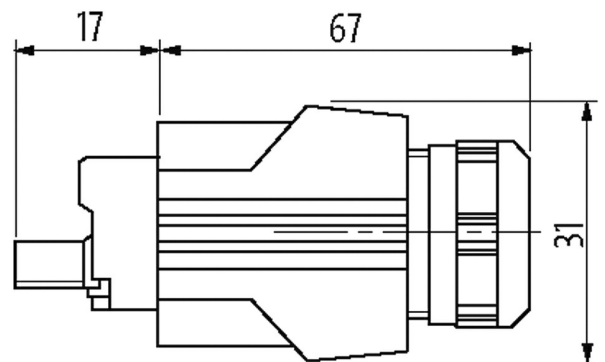[Link to Product](#)**Illustration**

Height: 36 mm

Product may differ from Image

Approvals**Form**

Form 99601

General data

Pollution Degree 2

Mating cycles ≥ 100

Temperature range -40...+70 °C


 
Technical Data

Operating voltage	max. 24 V AC/DC
Rated surge voltage	4.0 kV
Operating current per contact	max. 16 A
Connection cross section	0.75...2.5 mm ² (AWG 18...14)
Sealing range (cable Ø)	9...13 mm
Protection	IP65 and IP67 when plugged and screwed down (EN 60529)
Material	Zinc die casting, matte nickel plated

Commercial data

country of origin	PL
customs tariff number	85366990
EAN	4048879113915
eClass	27279221
Packaging unit	1

Sketch

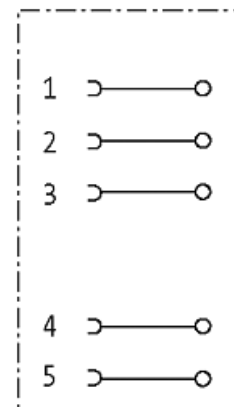

Product may differ from Image