

**PUSH PULL RJ45 4 POLE FIELD- WIREABLE**

Ethernet CAT5

Male straight

RJ45PP, 4-pole

IDC terminals

Connection cross section: 0.14...0.34 mm<sup>2</sup>

Push Pull

Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.

[Link to Product](#)**Illustration**

Product may differ from Image

**More Info****Form**

Form 99611

**General data**

Temperature range -40...+70 °C

**Technical Data**

Operating voltage max. 60 V DC

Operating current per contact max. 1.76 A

Transfer parameters CAT5, Class D (ISO/IEC 11801:2002), (EN 50173-1)

Transfer rate up to 100 Mbit/s full duplex

Connection cross section 0.14...0.34 mm<sup>2</sup> (AWG 26...22)

Sealing range (cable Ø) 4...11 mm

Protection IP65 and IP67 when plugged and screwed down (EN 60529)

**Commercial data**

country of origin RO

customs tariff number 85366990

EAN 4048879113908


eClass 27279221

Packaging unit 1


Sketch

Male

6 321

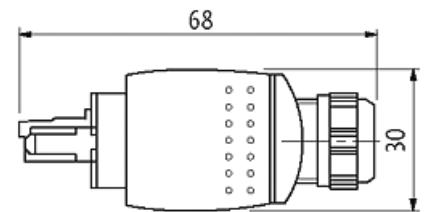

Height: 22 mm

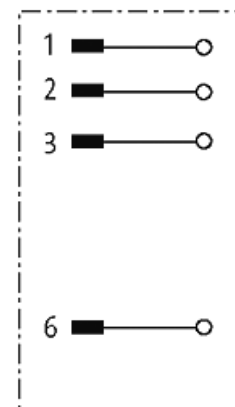

Product may differ from Image