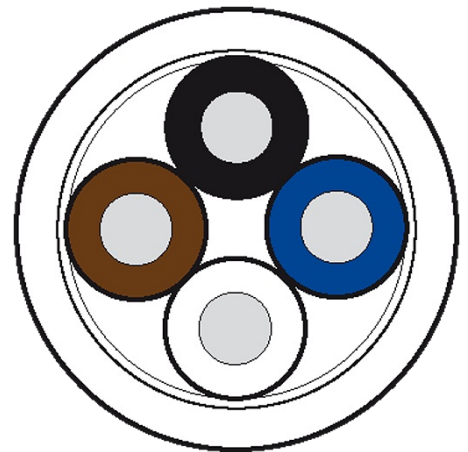


CABLE DRUM Ø 500MM

PUR 4X0.34 shielded GRAY, 500m

Cable drum (500 m)
PUR/PVC
4× 0.34 mm², gray
shielded

[Link to Product](#)**Illustration**

Product may differ from Image

Cables

Cable number	331
No./diameter of wires	4 × 0.34 mm ²
Wire isolation	PVC (br, wh, bl, bk)
Jacket Color	gray
Material (jacket)	PUR/PVC
Outer Ø	5.9 mm ±5%
Bend radius (fixed)	10× outer Ø
Bend radius (moving)	15× outer Ø
Temperature range (fixed)	-30...+80 °C
Temperature range (mobile)	-5...+70 °C
Shield	yes
Color (jacket)	gray
Approval (cable)	CE conform

Commercial data

country of origin	IT
customs tariff number	85444995
EAN	4048879313612
eClass	27062011
Packaging unit	1