

**T-coupler M12 male / M12 female V2A**

T-coupler

Male straight – females straight

M12 – M12, 5-pole

Parallel circuit


V2A nut/screw

Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.

[Link to Product](#)**Illustration**

Product may differ from Image

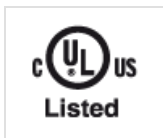**Approvals****Form**

Form 41141

**General data**

Temperature range -25...+85 °C

**Technical Data**

Operating voltage max. 60 V AC/DC

Operating current per contact max. 4 A

Locking of ports Screw thread (M12×1 mm) recommended torque 0.6 Nm, self-securing

Protection IP67 inserted and tightened (EN 60529)

Locking material Stainless steel 1.4305 (V2A)

**Commercial data**

country of origin DE




customs tariff number 85366990

EAN 4048879516242

eClass 27279221

Packaging unit 1

**Sketch**

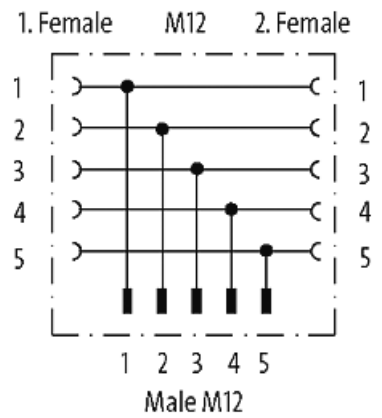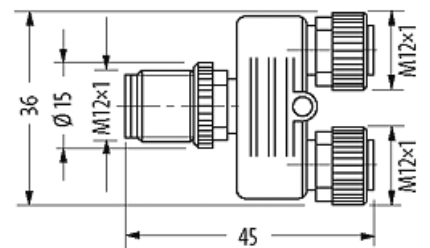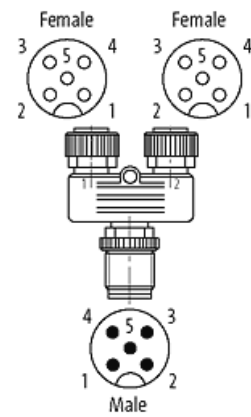

Product may differ from Image