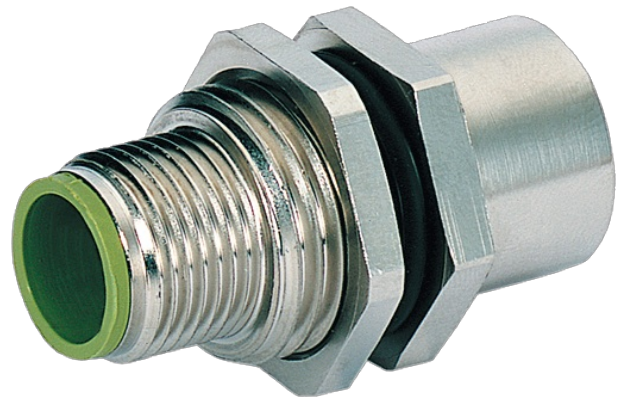


M12-PANEL FEED THROUGH 5POLE B CODED, V2A

Control cabinet entry system
 Male - female
 M12, 5-pole
 B-coded
 shielded
 Stainless steel 1.4305 (V2A)

[Link to Product](#)**Illustration**

Product may differ from Image

Form

Form 44111

General data

Mounting set M16×1.5 mm
 Temperature range -25...+85 °C

Technical Data

Operating voltage max. 60 V AC/DC
 Operating current per contact max. 4 A
 Locking of ports Screw thread (M12×1 mm) recommended torque 0.6 Nm, self-securing
 Protection IP67 inserted and tightened (EN 60529)
 Material Stainless steel 1.4305 (V2A)

Commercial data

country of origin CZ
 customs tariff number 85366990
 EAN 4048879483728
 eClass 27279221
 Packaging unit 1

Sketch

