

**M12 MALE 0° FIELD-WIREABLE SCREW V4A**5-pol. 6-8mm max. 0,75mm<sup>2</sup>**F&B**

Male straight

M12, 5-pole

Sealing range (cable Ø): 6...8 mm

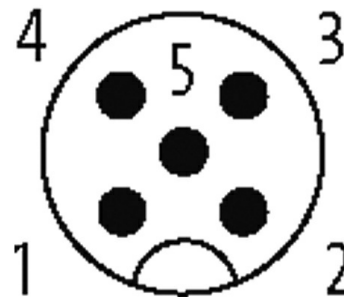
Stainless steel 1.4404 (V4A)

Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.

[Link to Product](#)**Illustration**

Male



Product may differ from Image

**Form**

Form 12761

**General data**

Temperature range -25...+85 °C

**Technical Data**

Operating voltage max. 125 V AC/DC

Operating current per contact max. 4 A

Connection cross section max. 0.75 mm<sup>2</sup>

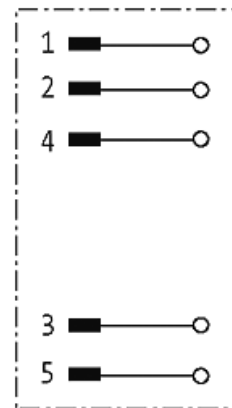
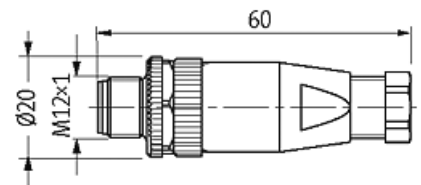
Sealing range (cable Ø) 6...8 mm

Locking of ports Screw thread (M12×1 mm) recommended torque 0.6 Nm, self-securing

Protection	IP67 inserted and tightened (EN 60529)
Locking material	Stainless steel 1.4404 (V4A)

**Commercial data**

country of origin	DE
customs tariff number	85366990
EAN	4048879110952
eClass	27279221
Packaging unit	1

**Sketch**

Product may differ from Image