

**M12 male 0° wireable scwv term. F&B PRO**5-pol. max.1,0mm<sup>2</sup> 3,5-6mm

M12 F&amp;B Pro

Male straight



5-pole

Screw terminals

The resistance to aggressive media should be individually tested for your application. Further details on request.

[Link to Product](#)**Illustration**

Male

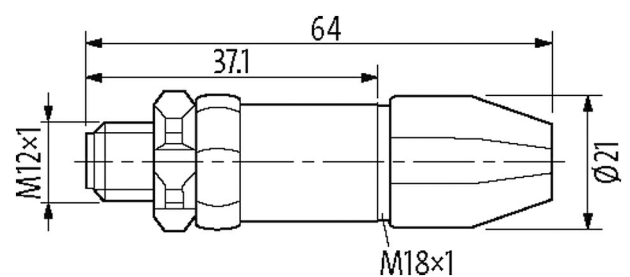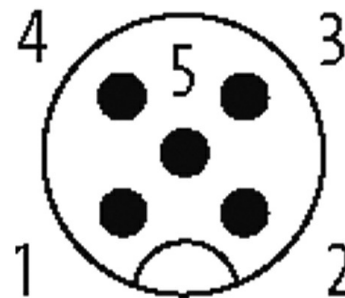

Product may differ from Image

**General data**

Safety class	2
Temperature range	-25...+100 °C
Material (gasket)	EPDM


**Technical Data**

Operating voltage	max. 60 V AC/DC
Operating current per contact	max. 4 A
Connection cross section	0.25...1.0 mm <sup>2</sup>
Sealing range (cable Ø)	3.5...6.0 mm
Locking of ports	Screw thread (M12×1 mm) recommended torque 0.6 Nm
Compression gland	M12 (SW19)
Protection	IP65, IP68, IP69K inserted and tightened (EN 60529)
Material	PA
Locking material	Stainless steel

#### Commercial data

country of origin	DE
customs tariff number	85366990
EAN	4048879804646
eClass	27279221
Packaging unit	1

#### Sketch

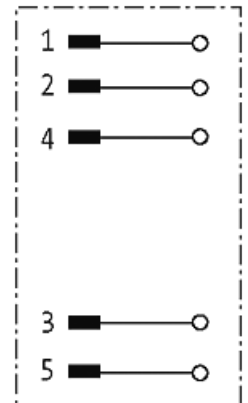

Product may differ from Image