

M12 MALE 0° SELF WIREABLE SCREW TERMINAL

5-pol. 0,14 - 1,5mm², 2,5-8mm cable diameter

AIDA conform

Male straight

M12, 5-pole

Screw terminals


Sealing range (cable Ø): 4...8 mm

Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.

[Link to Product](#)**Illustration**

Male

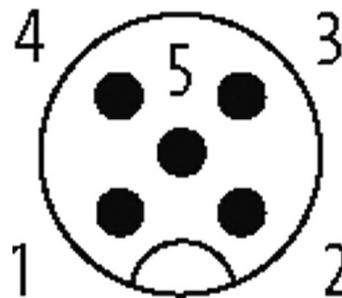

Product may differ from Image

Form

Form 12731

General data

Pollution Degree 3

Temperature range -30...+85 °C

Technical Data

Operating voltage max. 60 V AC/DC

Operating current per contact max. 4 A



Material group IEC 60664-1, category III

Coding	A-coded
Sealing range (cable Ø)	4...8 mm
Locking of ports	Screw thread (M12×1 mm) recommended torque 0.6 Nm, self-securing
Protection	IP67 inserted and tightened (EN 60529)
Material	PA

Commercial data

country of origin	CZ
customs tariff number	85366990
EAN	4048879642125
eClass	27279221
Packaging unit	1

Sketch

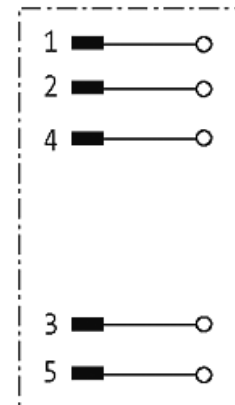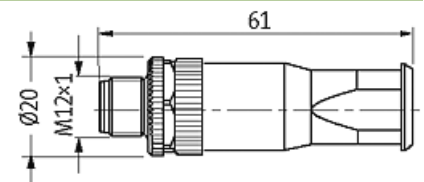

Product may differ from Image