

**M12 FEMALE 0° SELF WIREABLE SCREW TERMINAL**5-pol. 0,14 - 1,5mm<sup>2</sup>, 2,5-8mm cable diameter

AIDA conform

Female straight

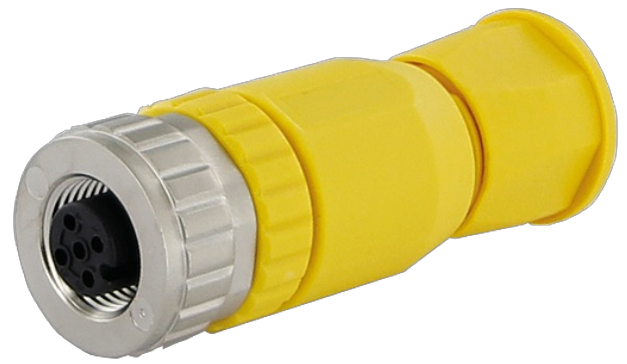
M12, 5-pole

Screw terminals

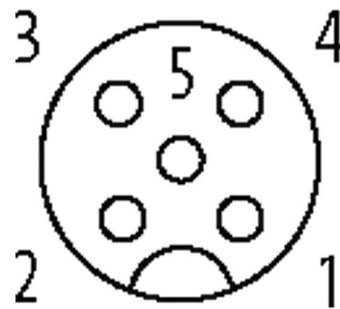
Sealing range (cable Ø): 4...8 mm

Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.

[Link to Product](#)**Illustration**

Female



Product may differ from Image

**Form**

Form 12931

**General data**

Pollution Degree 3

Temperature range -30...+85 °C

Material (gasket) FKM

**Technical Data**

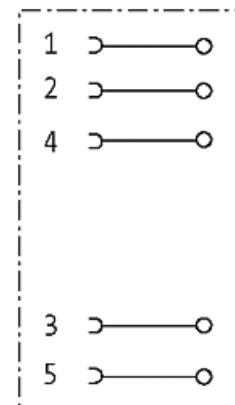
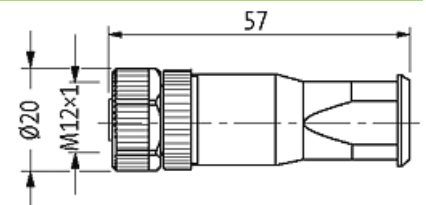
Operating voltage max. 60 V AC/DC

Operating current per contact max. 4 A

Material group	IEC 60664-1, category III
Coding	A-coded
Sealing range (cable Ø)	4...8 mm
Locking of ports	Screw thread (M12×1 mm) recommended torque 0.6 Nm, self-securing
Protection	IP67 inserted and tightened (EN 60529)
Material	PA

**Commercial data**

country of origin	CZ
customs tariff number	85366990
EAN	4048879661898
eClass	27279221
Packaging unit	1

**Sketch**

Product may differ from Image