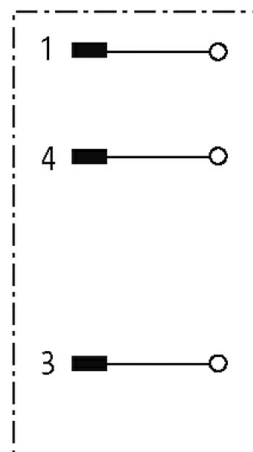
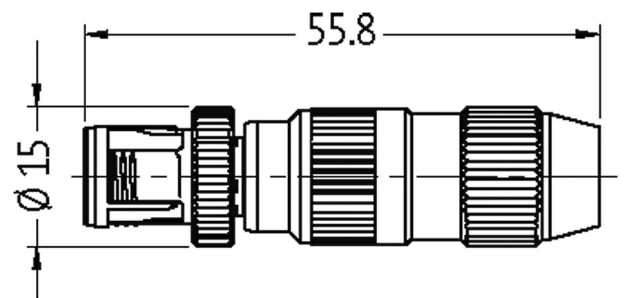


**MOSA MQ12 MALE 0° FIELD-WIREABLE (IDC)**3-pol. 0.25...0.5mm<sup>2</sup>

Male straight

MQ12, 3-pole

IDC terminals

Connection cross section: 0.25...0.5 mm<sup>2</sup>[Link to Product](#)**Illustration**

Product may differ from Image

**Form**

Form 12461

**General data**

Temperature range -25...+85 °C

**Technical Data**

Operating voltage	max. 32 V AC/DC
Rated surge voltage	0.8 kV
Operating current per contact	max. 4 A
Material group	IEC 60664-1, category II
Connection cross section	0.25...0.5 mm <sup>2</sup> (conductor diameter min. 0.1 mm)
Sealing range (cable Ø)	4...5.1 mm
Wire isolation	PVC, PP, TPE
Outer wire Ø	1.2...1.6 mm
Protection	IP67 inserted and tightened (EN 60529)

#### Commercial data

country of origin	DE
customs tariff number	85366990
EAN	4048879106672
eClass	27279218
Packaging unit	1

#### Sketch

Male



Product may differ from Image