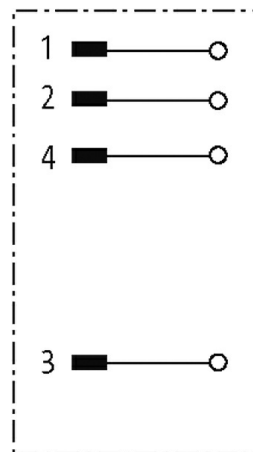


MOSA MQ12 MALE 0° FIELD-WIREABLE (IDC)4-pol. 0.5...1.0mm²

Male straight

MQ12, 4-pole

IDC terminals

Connection cross section: 0.5...1.0 mm²[Link to Product](#)**Illustration**

Product may differ from Image

Form

Form 12521

General data

Temperature range -25...+85 °C

Technical Data

Operating voltage max. 250 V AC/DC

Rated surge voltage 2.5 kV

Operating current per contact max. 4 A

Material group IEC 60664-1, category III

Connection cross section 0.5...1.0 mm² (conductor diameter min. 0.1 mm)

Sealing range (cable Ø) 5.5...8 mm

Wire isolation PVC, PP, TPE

Outer wire Ø 1.6...2.0 mm


Protection IP67 inserted and tightened (EN 60529)

Commercial data

country of origin	DE
customs tariff number	85366990
EAN	4048879106634
eClass	27279218
Packaging unit	1

Sketch

Male

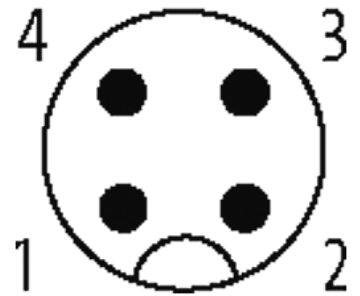

Product may differ from Image