

MOSA MQ12 FEMALE 0° FIELD-WIREABLE (IDC)3-pol. 0.25...0.5mm²

Female straight
MQ12, 3-pole
IDC terminals
Connection cross section: 0.25...0.5 mm²

[Link to Product](#)**Illustration**

Product may differ from Image

Form

Form 12581

General data

Temperature range -25...+85 °C

Technical Data

Operating voltage max. 32 V AC/DC

Rated surge voltage 0.8 kV

Operating current per contact max. 4 A

Material group IEC 60664-1, category II

Connection cross section 0.25...0.5 mm² (conductor diameter min. 0.1 mm)

Sealing range (cable Ø) 4...5.1 mm

Wire isolation PVC, PP, TPE

Outer wire Ø 1.2...1.6 mm

Protection IP67 inserted and tightened (EN 60529)

Commercial data

country of origin DE

customs tariff number 85366990



EAN 4048879106627

eClass 27279218

Packaging unit 1

Sketch

Female

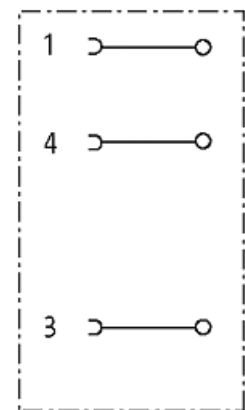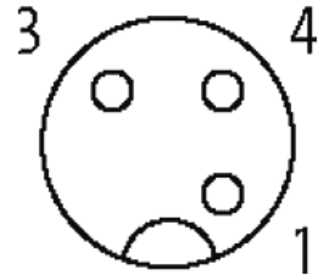

Product may differ from Image