

**MOSA MQ12 FEMALE 0° FIELD-WIREABLE (IDC)**4-pol. 0.25...0.5mm<sup>2</sup>

Female straight  
MQ12, 4-pole  
IDC terminals  
Connection cross section: 0.25...0.5 mm<sup>2</sup>

[Link to Product](#)**Illustration**

Product may differ from Image

**Form**

Form 12601

**General data**

Temperature range -25...+85 °C

**Technical Data**

Operating voltage max. 32 V AC/DC

Rated surge voltage 0.8 kV

Operating current per contact max. 4 A

Material group IEC 60664-1, category II

Connection cross section 0.25...0.5 mm<sup>2</sup> (conductor diameter min. 0.1 mm)

Sealing range (cable Ø) 4...5.1 mm

Wire isolation PVC, PP, TPE

Outer wire Ø 1.2...1.6 mm

Protection IP67 inserted and tightened (EN 60529)

**Commercial data**

country of origin DE

customs tariff number 85366990



EAN 4048879106610

eClass 27279218

Packaging unit 1

**Sketch**

## Female

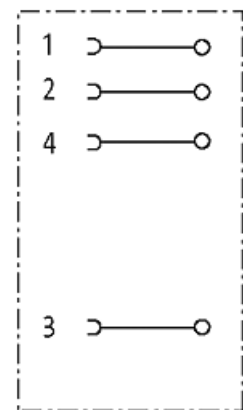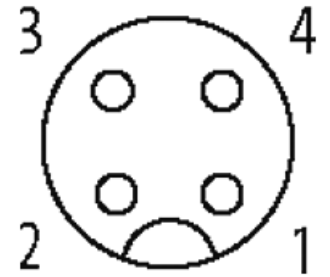

Product may differ from Image