

**MOSA MQ12 FEMALE 0° FIELD-WIREABLE (IDC)**3-pol. 0.5...1.0mm<sup>2</sup>

Female straight  
MQ12, 3-pole  
IDC terminals  
Connection cross section: 0.5...1.0 mm<sup>2</sup>

[Link to Product](#)**Illustration**

Product may differ from Image

**Form**

Form 12621

**Technical Data**


Operating voltage	max. 250 V AC/DC
Operating current per contact	max. 4 A
Connection cross section	0.5...1.0 mm <sup>2</sup> (conductor diameter min. 0.1 mm)
Outer wire Ø	1.6...2.0 mm
Protection	IP67 inserted and tightened (EN 60529)
Sealing range (cable Ø)	5.5...8 mm
Wire isolation	PVC, PP, TPE

**Commercial data**

country of origin	DE
customs tariff number	85366990
EAN	4048879106603
eClass	27279218
Packaging unit	1

**Sketch**

## Female

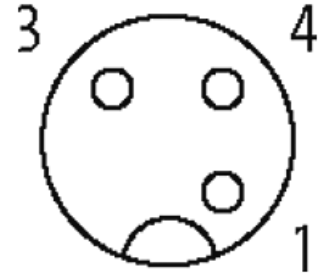

Product may differ from Image