

MOSA MQ12 FEMALE 0° FIELD-WIREABLE (IDC)4-pol. 0.5...1.0mm²

Female straight
MQ12, 4-pole
IDC terminals
Connection cross section: 0.5...1.0 mm²

[Link to Product](#)**Illustration**

Product may differ from Image

Form

Form 12641

General data

Temperature range -25...+85 °C

Technical Data



Operating voltage	max. 250 V AC/DC
Rated surge voltage	2.5 kV
Operating current per contact	max. 4 A
Material group	IEC 60664-1, category III
Connection cross section	0.5...1.0 mm ² (conductor diameter min. 0.1 mm)
Sealing range (cable Ø)	5.5...8 mm
Wire isolation	PVC, PP, TPE
Outer wire Ø	1.6...2.0 mm
Protection	IP67 inserted and tightened (EN 60529)

Commercial data

country of origin	DE
customs tariff number	85366990
EAN	4048879106580
eClass	27279218
Packaging unit	1

Sketch

Female

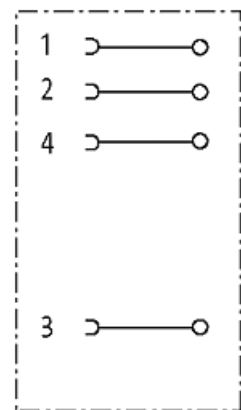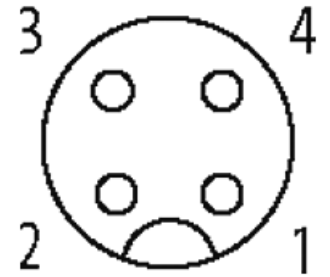

Product may differ from Image