

JUNIOR TIMER VALVE PLUG 0°

PUR 2x0,75 black 15m

Xtreme - Outdoor

Female straight

0...230 V AC/DC

without components

Stainless steel 1.4305 (V2A)


Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.

Further cable lengths on request.

[Link to Product](#)

Illustration

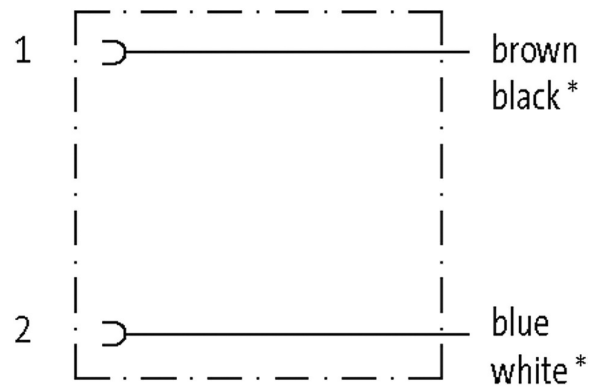

* for cable type (740)



Product may differ from Image

| Form | |
|-------------------------------|--|
| Form | 70001 |
| General data | |
| Temperature range | -25...+85 °C, depending on cable quality |
| Cables | |
| Cable number | 750 |
| No./diameter of wires | 2× 0.75 mm ² |
| Wire isolation | PVC (br, bl) |
| Jacket Color | black |
| Material (jacket) | PUR/PVC |
| Outer Ø | 5.9 mm ±5% |
| Bend radius (moving) | 15× outer Ø |
| Temperature range (fixed) | -40...+80 °C |
| Temperature range (mobile) | -5...+80 °C |
| Cable identification | 750 |
| Approval (cable) | CE conform |
| Cable weight [g/m] | 48,40 |
| Material (wire) | Cu wire, bare |
| Resistor (core) | max. 26 Ω/km (20 °C) |
| Single wire Ø (core) | 0.2 mm |
| Construction (core) | 24× 0.2 mm (multi-strand wire class 5) |
| Diameter (core) | 2× 0.75 mm ² |
| AWG | similar to AWG 18 |
| Material (wire isolation) | PVC |
| Color/numbering of wires | br, bl |
| Stranding combination | 2 wires twisted |
| Shield | no |
| Material (jacket) | PUR/PVC |
| Outer-Ø (jacket) | 5.9 mm ±5% |
| Color (jacket) | black |
| chemical resistance | good resistance to oil, gasoline and chemicals |
| Nominal voltage | 300 V AC |
| Test voltage | 2000 V AC |
| Temperature range (fixed) | -40...+80 °C |
| Temperature range (mobile) | -5...+80 °C |
| Bend radius (moving) | 15× outer Ø |
| Technical Data | |
| Operating voltage | max. 230 V AC/DC |
| Operating current per contact | max. 4 A |
| Protection | IP65 inserted and tightened (EN 60529) |
| Housing | Black plastic, flame retardant |
| Locking material | Stainless steel 1.4305 (V2A) |
| Commercial data | |
| country of origin | DE |
| customs tariff number | 85444290 |
| EAN | 4048879373463 |
| eClass | 27279218 |

Packaging unit

1